


Garant GRIDLINE

Base cabinet with drawer, Viewing window sliding doors, 26×14G, Height: 750mm

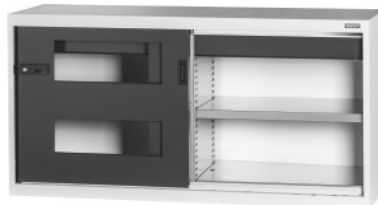

Order data

Order number	940187 750
GTIN	4062406067007
Item class	9GI

Description

Version:

Equipped cabinet in 60×20G, with drawers 26×14G. Mountings for shelves at 25 mm intervals. Sliding doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock. Locks the sliding doors in the end positions (open/closed). **Levelling base** for base cabinets, with 8 individually adjustable feet to compensate for unevenness in the floor. In the base cabinet the handle is mounted in the upper part of the door; in the top-mounted cabinet it is in the lower part of the door.

drawers with front height 125 mm.

Supplied with:

Cabinet with shelves and drawers.

Colour:

Body and drawer cabinet body RAL 7035 light grey, doors and drawer fronts RAL 7016 anthracite **powder-coated**.

Note:

For storage shelves and accessories for GridLine cabinets see No. 940501 – 940710 and Group 95. According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

Technical description

Electronic locking system can be retrofitted	yes
Drawer usable depth in G	14

Drawer usable area in G	26×14
Width	1500 mm
Usable height	613 mm
Width in G	60
Number of drawers	2
Depth	500 mm
Drawer usable width in G	26
Drawer runner extension (partial/full extension)	100 %
Number of shelves	2
ComfortClose	no
Handle positioning	top
Depth in G	20
Weight	90 kg
Drawer usable width	650 mm
Height	750 mm
Drawer/pull-out shelf load capacity	75 kg
Shelf load capacity / maximum distributed shelf load (on metal)	100 kg
Drawer usable depth	350 mm
Material thickness	0.9 mm
Cabinet housing internal load capacity	1000 kg
Height adjustment interval	25 mm
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Drawer usable width × usable depth in G	26×14G
Type of cabinet	Base cabinet
Type of product	Cabinet with shelves

Accessories

Drawer for sliding door cabinets,Width 30G Drawer front height 300 mm	940651 300
Cover made of laminated wood Dimension in G 60X20	951985 60X20
Cover made of bamboo Dimension in G 60X20	951980 60X20
Comfort Close drawer closure damping system Load capacity of the drawer 75 kg	950180 75
Drawer for sliding door cabinets,Width 30G Drawer front height 100 mm	940651 100
Drawer for sliding door cabinets,Width 30G Drawer front height 200 mm	940651 200
Inclined shelf for cabinet / compartment width in G 30	940560 30
Drawer for sliding door cabinets,Width 30G Drawer front height 125 mm	940651 125
Lock plate for GridLine Type GP21	914227 GP21
Extended lighting set for GridLine cabinets withSliding doors, width 60G for cabinet height 750/800 mm	940514 750/800
Storage shelf slotted for cabinet / compartment width in G 30	940552 30
Storage shelf200 kg for cabinet / compartment width in G 30	940590 30
Storage shelf for cabinet / compartment width in G 30	940550 30
Base with removable fascia, depth 20G,Height 150 mm Cabinet casing in G 60	958146 60
Drawer for sliding door cabinets,Width 30G Drawer front height 75 mm	940651 75
Drawer for sliding door cabinets,Width 30G Drawer front height 150 mm	940651 150