


Garant GRIDLINE

## Top-mounted cabinet with Viewing window sliding doors, Height: 500mm

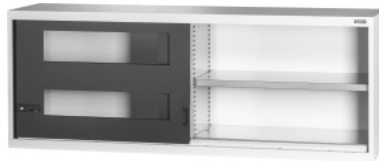

### Order data

Order number	940217 500
GTIN	4062406070182
Item class	9GI

### Description

#### Version:

Equipped cabinet in 80×20G. Mountings for shelves at 25 mm intervals. Sliding doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock. Locks the sliding doors in the end positions (open/closed). **Levelling base** for base cabinets, with 8 individually adjustable feet to compensate for unevenness in the floor. In the base cabinet the handle is mounted in the upper part of the door; in the top-mounted cabinet it is in the lower part of the door.

#### Supplied with:

Cabinet with storage shelves.

#### Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

#### Note:

For storage shelves and accessories for GridLine cabinets see No. 940501 – 940710 and Group 95. According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

### Technical description

Weight	70 kg
Usable height	363 mm
Width in G	80
ComfortClose	no
Handle positioning	bottom

Height	500 mm
Electronic locking system can be retrofitted	yes
Number of shelves	2
Depth	500 mm
Shelf load capacity / maximum distributed shelf load (on metal)	100 kg
Cabinet fronts	Viewing window sliding door
Width	2000 mm
Depth in G	20
Material thickness	0.9 mm
Cabinet housing internal load capacity	1000 kg
Height adjustment interval	25 mm
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of cabinet	Add-on cabinet
Type of product	Cabinet with shelves

## Accessories

Drawer for sliding door cabinets,Width 40G Drawer front height 100 mm	940652 100
Lock plate for GridLine Type GP21	914227 GP21
Drawer for sliding door cabinets,Width 40G Drawer front height 300 mm	940652 300
Storage shelf slotted for cabinet / compartment width in G 40	940552 40
Drawer for sliding door cabinets,Width 40G Drawer front height 125 mm	940652 125
Storage shelf200 kg for cabinet / compartment width in G 40	940590 40

Drawer for sliding door cabinets,Width 40G Drawer front height 75 mm	940652 75
Storage shelf for cabinet / compartment width in G 40	940550 40
Shelf clip set for GridLine cabinets20 pieces Type F	940559 F
Drawer for sliding door cabinets,Width 40G Drawer front height 200 mm	940652 200
Drawer for sliding door cabinets,Width 40G Drawer front height 150 mm	940652 150
Inclined shelf for cabinet / compartment width in G 40	940560 40