


Garant GRIDLINE

## Base cabinet with Viewing window sliding doors, Height: 1250mm

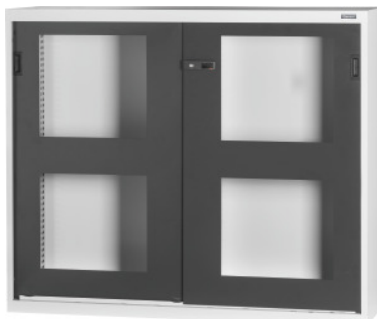

### Order data

Order number	940887 1250
GTIN	4062406071257
Item class	9GI

### Description

#### Version:

Empty cabinet in 60×20G. Suitable drawers: 26×14G (please order these separately). Mountings for shelves at 25 mm intervals. Doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock. Levelling base with adjustable feet to compensate for unevenness in the floor.

#### Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

#### Note:

For storage shelves and accessories for GridLine cabinets see No. 940501 – 940710 and Group 95. According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

### Technical description

Width in G	60
Cabinet fronts	Viewing window sliding door
Type of cabinet	Base cabinet
ComfortClose	no
Depth in G	20

Weight	93 kg
Electronic locking system can be retrofitted	yes
Height	1250 mm
Width	1500 mm
Handle positioning	top
Usable height	1095 mm
Depth	500 mm
Version	for individual configuration
Material thickness	0.9 mm
Cabinet housing internal load capacity	1000
Height adjustment interval	25
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Cabinet with shelves

## Accessories

Inclined shelf for cabinet / compartment width in G 30	940560 30
Drawer for sliding door cabinets,Width 30G Drawer front height 125 mm	940651 125
Storage shelf slotted for cabinet / compartment width in G 30	940552 30
Drawer for sliding door cabinets,Width 30G Drawer front height 300 mm	940651 300
Storage shelf200 kg for cabinet / compartment width in G 30	940590 30
Drawer for sliding door cabinets,Width 30G Drawer front height 75 mm	940651 75
Drawer for sliding door cabinets,Width 30G Drawer front height 150 mm	940651 150

Storage shelf for cabinet / compartment width in G 30	940550 30
Extended lighting set for GridLine cabinets with Sliding doors, width 60G for cabinet height 1000/1250 mm	940514 1000/1250
Drawer for sliding door cabinets, Width 30G Drawer front height 100 mm	940651 100
Extended lighting set for GridLine cabinets with Sliding doors, width 60G for cabinet height 1500 mm	940514 1500
Lock plate for GridLine Type GP21	914227 GP21
Drawer for sliding door cabinets, Width 30G Drawer front height 200 mm	940651 200