


Garant GRIDLINE

## Large-capacity / heavy-duty cabinet with Viewing window sliding door, Height: 1000mm

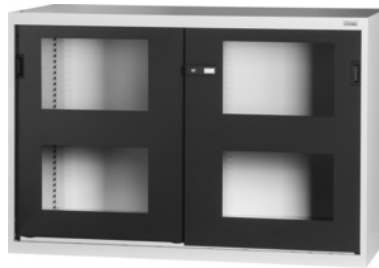

### Order data

Order number	942747 1000
GTIN	4062406072704
Item class	9GI

### Description

#### Version:

Empty cabinet in 60×28G. Suitable drawers: 26×20G (please order these separately). Mountings for shelves at 25 mm intervals. Doors reinforced on the inside and can be locked by 2-component Haptoprene® handle using a cylinder lock.

#### Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

#### Note:

For storage shelves and accessories for GridLine large-capacity cabinets and heavy-duty cabinets see No. 942530 – 942610 and Group 95.

**Use as a heavy-duty cabinet is only possible in conjunction with heavy load shelf No. 942610.**

According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

### Technical description

Width in G	60
ComfortClose	no
Type of cabinet	Base cabinet
Usable height	863 mm

Handle positioning	top
Height	1000 mm
Depth	700 mm
Weight	119 kg
Cabinet fronts	Viewing window sliding door
Electronic locking system can be retrofitted	yes
Width	1500 mm
Depth in G	28
Version	for individual configuration
Material thickness	0.9 mm
Cabinet housing internal load capacity	1600
Height adjustment interval	25
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Large-capacity cabinet

## Accessories

Lock plate for GridLine Type GP21	914227 GP21
Drawers for sliding-door large-capacity cabinets and heavy-duty cabinetsWidth 30G Drawer front height 75 mm	942580 75
Drawers for sliding-door large-capacity cabinets and heavy-duty cabinetsWidth 30G Drawer front height 300 mm	942580 300
Drawers for sliding-door large-capacity cabinets and heavy-duty cabinetsWidth 30G Drawer front height 200 mm	942580 200
Drawers for sliding-door large-capacity cabinets and heavy-duty cabinetsWidth 30G Drawer front height 100 mm	942580 100

Drawers for sliding-door large-capacity cabinets and heavy-duty cabinets Width 30G Drawer front height 150 mm	942580 150
Extended lighting set for GridLine cabinets with sliding doors, width 60G for cabinet height 1000/1250 mm	940514 1000/1250
Drawers for sliding-door large-capacity cabinets and heavy-duty cabinets Width 30G Drawer front height 125 mm	942580 125
Storage shelf with brackets 100 kg for cabinet / compartment width in G 30	942530 30
Inclined shelf Form for cabinet / compartment width in G 30	942550 30