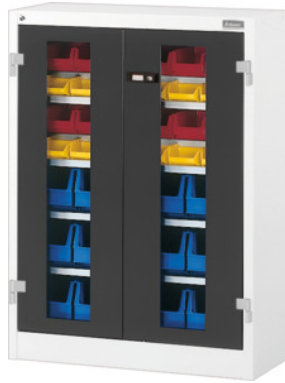


Garant
Shelving cabinet with viewing window swing doors, Height: 1000mm

Order data

Order number	944005 1000
GTIN	4062406073398
Item class	9GI

Description
Version:

Mountings for storage shelves at 25-mm intervals.

Equipped shelf cabinet in 30×11G.

Doors reinforced on the inside and can be locked by 2-component Haptoprene® push handle using a cylinder lock.

Fitted with:

Number of storage bins: 12 × No. 963321 size SB6; 12 × No. 963321 size SB5; 12 × No. 963321 size SB4

Supplied with:

Cabinet with shelves and open storage bins.

Colour:

Body RAL 7035 light grey, doors RAL 7016 anthracite **powder-coated**.

Note:

- **For single open storage bins see No 963321.**
- **For individual storage shelves see No. 944061, 944065.**

According to the TÜV GS certification, it is essential that all cabinets are secured against tipping over.

Technical description

Cabinet fronts	Viewing window swing door
Height	1000 mm
Number of shelves	4
Width	750 mm
Shelf load capacity / maximum distributed shelf load (on metal)	80 kg
Weight	47 kg
Depth	275 mm
Usable height	845 mm
Depth in G	11
Width in G	30
Material thickness	0.9 mm
Cabinet housing internal load capacity	500 kg
Door opening angle	250 degrees
Height adjustment interval	25 mm
Cylinder lock	modular barrel
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Type of product	Racking cupboard

Accessories

Stepped shelves for shelving cabinets, depth 11 G for cabinet width in G 30	944065 30
Slide handle for GridLine Type GP11	914226 GP11
Shelf clip set for GridLine cabinets 20 pieces Type F	940559 F
Storage shelves for shelving cabinets, depth 11 G for cabinet width in G 30	944061 30