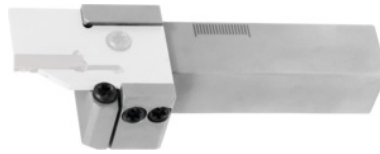


**Garant**
**eco VARIO-LINE toolholder, left-hand, Shank height h: 20mm**

**Order data**

Order number	273871 20
GTIN	4045197702265
Item class	21W

**Description**
**Suitable for:**

eco blade carrier No. 273875.

**Supplied with:**

Including assembly screws.

**Note:**

Coolant transfer only in conjunction with GARANT eco-system toolholders No. 317900 – 319886.

$L = L_1 + L_3$  (eco blade carrier).

Through-coolant: yes

Functional width  $L_4$ : 25 mm

$L_1$ : 93.5 mm

$L_2$ : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

**Technical description**

Functional width $L_4$	25 mm
Shank height h	20 mm
Screw	279815 9 (TX25; 6.0 Nm)
$L_2$	24.5 mm
$L_1$	93.5 mm
Series	Eco

Application type	left-hand
Through-coolant	yes
Type of product	Clamping toolholder

---

## Accessories

Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
Clamping screw	279910
PrecisionBit for Torx®, 1/4 inch E 6.3 Torx® profile TX10	674248 TX10
Clamping screw Type 9	279815 9