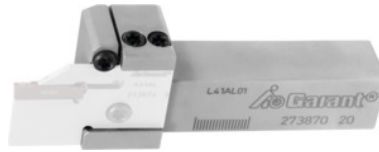


Garant
eco VARIO-LINE toolholder, right-hand, Shank height h: 25mm

Order data

Order number	273870 25
GTIN	4045197702241
Item class	21W

Description
Suitable for:

eco blade carrier No. 273874.

Supplied with:

Including assembly screws.

Note:

Coolant transfer only in conjunction with GARANT eco-system toolholders No. 317900 – 319886.

 $L = L_1 + L_3$ (eco blade carrier).

Through-coolant: yes

 Functional width L_4 : 30 mm

 L_1 : 95.5 mm

 L_2 : 24.5 mm

Screw: 279815 9 (TX25; 6.0 Nm)

Technical description

L_2	24.5 mm
Functional width L_4	30 mm
Screw	279815 9 (TX25; 6.0 Nm)
Shank height h	25 mm
L_1	95.5 mm
Series	Eco

Application type	right-hand
Through-coolant	yes
Type of product	Clamping toolholder

Accessories

Clamping screw	279910
Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
Clamping screw Type 9	279815 9
PrecisionBit for Torx®, 1/4 inch E 6.3 Torx® profile TX10	674248 TX10