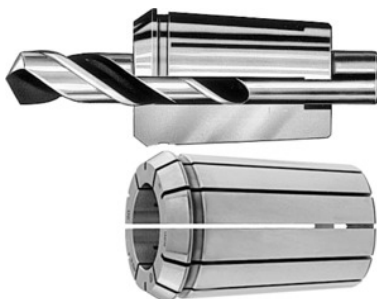


**FAHRION®**  
FAHREYOND FINESSION

## Dados do pedido

|                  |               |
|------------------|---------------|
| Número do pedido | 309550 4      |
| GTIN             | 2050001704498 |
| Classe de artigo | 39Y           |

## Descrição

### Modelo:

Spring steel, through hardened and ground. The through bore (longer clamping range than DIN collets) increases the clamping force. More slits than DIN collets, giving a greater insertion depth in the collet chuck. Suitable for jobber drills, for clamping on the guide land **Clamping range = Nominal size down to minus 0.5 mm.** 5 or 6 slits each end.

## Descrição técnica

|                             |                 |
|-----------------------------|-----------------|
| Ø de fixação nominal d      | 4 mm            |
| para mandril                | 2 - 25 mm       |
| Atributo do nome do produto | 2 # 25 mm       |
| Norma                       | ISO 10897       |
| Tipo                        | 462 E           |
| Ø exterior D                | 35,05 mm        |
| Comprimento total L         | 52 mm           |
| Tipo de produto             | Pinça de aperto |

