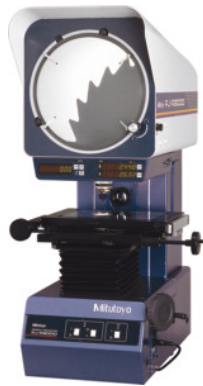


**Mitutoyo**

## Dados do pedido

Número do pedido	493510 A3005
GTIN	
Classe de artigo	44C

## Descrição

### Modelo:

**Projector for the exact transillumination and incident light inspection** of small to medium-sized components. **Universal tool** for use in production, laboratory, inspection, and grinding shop.

- **Standard lens 10×. 20× and 50× lenses available as optional accessories. Maximum distortion of the lenses 0.2 %.**
- **Vertical, rotating 315 mm cross-hair screen with built-in digital angle display, switching for reading in degrees or decimal.**
- **The telecentric lighting system guarantees a vertical and even illumination of the image field.**
- **Halogen transillumination and incident illumination integral in the housing.**
- **Sturdy coordinate measurement table, with quick adjustment in both axes.**
- **Built-in digital display (with data output) guarantees reliable, error-free measuring.**
- **For measuring lengths, angles, curves, and radii.**

## Descrição técnica

Largura	550 mm
---------	--------

Leitura	0,001 mm
Altura	1080 mm
Peso	116 kg
Faixa de medição do eixo y	50 mm
Ø do monitor	315 mm
peso máximo da peça	8 kg
Comprimento	760 mm
Faixa de medição do eixo x	150 mm
Designação do fabricante	PJ-A3005F-150
Alimentação de energia	A energia elétrica
Tipo de produto	Projetor de perfil