


LINDSTRÖM

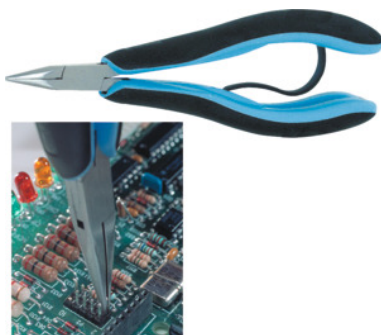

Dados do pedido

Número do pedido	726140 150
GTIN	7314150103249
Classe de artigo	73M

Descrição

Modelo:

Slim shape with narrow jaws. Jaws with rounded outer edges. Precision box joint with extra long slides for maximum stability with minimum friction. Mirror-polished head and joint. **Suitable for ESDs**, with ergonomic **2-component** grips. The patented opening spring reduces the resistance when closing the pliers, therefore the force applied to the component can be accurately gauged. Snipe nose, smooth internal jaws.

Descrição técnica

Largura da cabeça	9,6 mm
comprimento total	150 mm
Comprimento do mordente	20 mm
Propriedade eletrostática	EGB/ESD
Forma da boca	mordentes ovais/ pontagudos, interior liso
Modelo do mordente	interior liso
Punho	Manga para punho bicomponente

Método de produção	Arestas de corte temperadas por indução (45 – 48 HRC)
Material	Aço para rolamentos de esferas de alto desempenho
Superfície	com polimento espelhado
com mola de abertura	sim
Tipo de produto	Alicate de pontas chatas